

Descripción del artículo/Imágenes del producto



Descripción


Material:

Acero para temple y revenido.

Versión:

Tratado en caliente y bruñido.

Planos

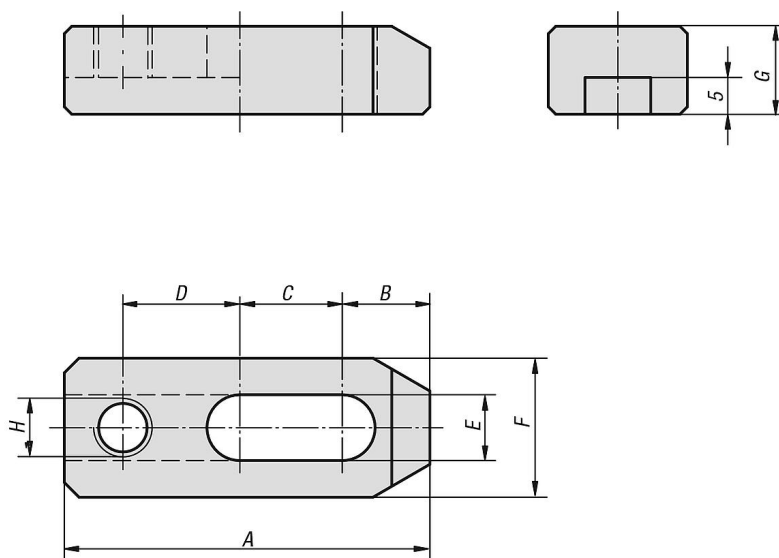

Nuestros productos

| Referencia | A | B | C | D | E | F | G | H |
|-------------|-----|----|----|----|----|----|----|-----|
| 04055-08040 | 40 | 10 | 6 | 16 | 9 | 19 | 12 | M8 |
| 04055-08050 | 50 | 12 | 14 | 16 | 9 | 19 | 12 | M8 |
| 04055-08063 | 63 | 12 | 27 | 16 | 9 | 19 | 12 | M8 |
| 04055-10050 | 50 | 12 | 8 | 20 | 11 | 25 | 12 | M10 |
| 04055-10063 | 63 | 15 | 18 | 20 | 11 | 25 | 12 | M10 |
| 04055-10080 | 80 | 15 | 32 | 23 | 11 | 25 | 16 | M10 |
| 04055-10100 | 100 | 15 | 40 | 35 | 11 | 25 | 16 | M10 |
| 04055-10125 | 125 | 15 | 50 | 50 | 11 | 25 | 16 | M10 |
| 04055-12063 | 63 | 14 | 14 | 24 | 13 | 32 | 16 | M12 |
| 04055-12080 | 80 | 20 | 25 | 24 | 13 | 32 | 16 | M12 |
| 04055-12100 | 100 | 20 | 40 | 29 | 13 | 32 | 19 | M12 |
| 04055-12125 | 125 | 20 | 50 | 44 | 13 | 32 | 19 | M12 |
| 04055-12160 | 160 | 20 | 60 | 69 | 13 | 32 | 19 | M12 |
| 04055-16080 | 80 | 18 | 17 | 30 | 17 | 38 | 19 | M16 |
| 04055-16100 | 100 | 25 | 30 | 30 | 17 | 38 | 25 | M16 |
| 04055-16125 | 125 | 25 | 45 | 40 | 17 | 38 | 25 | M16 |
| 04055-16160 | 160 | 25 | 65 | 55 | 17 | 38 | 25 | M16 |
| 04055-20160 | 160 | 32 | 60 | 52 | 21 | 50 | 25 | M20 |
| 04055-20200 | 200 | 32 | 80 | 72 | 21 | 50 | 25 | M20 |

