

Descripción del artículo/Imágenes del producto



Descripción

Material:


Acero o acero inoxidable 1.4404.

Versión:

Acero galvanizado.

Acero inoxidable con acabado natural.

Planos

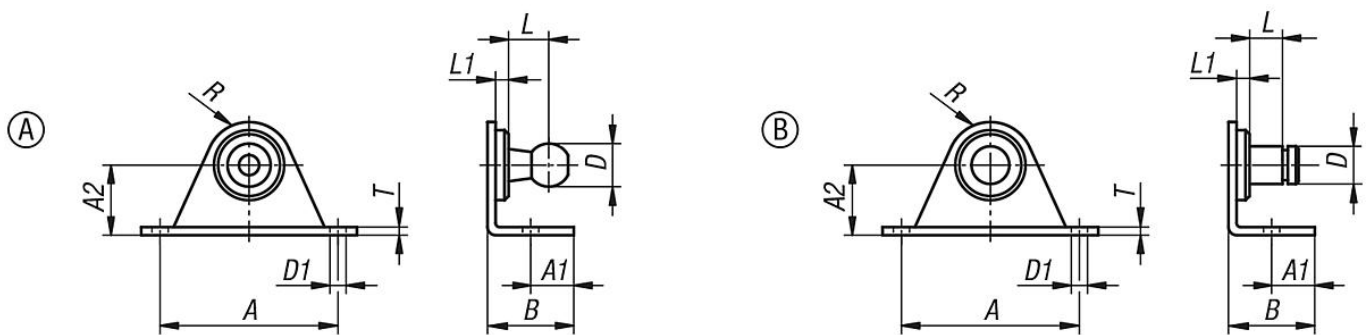

Nuestros productos

Referencia	Material del cuerpo de base	Forma	A	A1	A2	B	D	D1	L	L1	R	T	Estabilidad N
27657-00810	Acero	A	19	4,25	10	10	8	3,4	8	3	4	1,5	180
27657-00816	Acero	A	40	10	16	20	8	4,3	8	3	10	2	500
27657-01016	Acero	A	40	10	16	20	10	4,3	9	3	10	2	800
27657-01316	Acero	A	40	10	16	20	13	4,3	9,5	3	10	2	1200
27657-008101	Acero inoxidable	A	19	4,25	10	10	8	3,4	8	3	4	1,5	180
27657-008161	Acero inoxidable	A	40	10	16	20	8	4,3	8	3	10	2	500
27657-010161	Acero inoxidable	A	40	10	16	20	10	4,3	9	3	10	2	800
27657-013161	Acero inoxidable	A	40	10	16	20	13	4,3	9,5	3	10	2	1200
27657-10410	Acero	B	19	4,25	10	10	4	3,4	5	2	4	1,5	180
27657-10610	Acero	B	19	4,25	10	10	6	3,4	7	4	4	1,5	180
27657-10616	Acero	B	40	10	16	20	6	4,3	7	4	10	2	500
27657-10816	Acero	B	40	10	16	20	8	4,3	11	5	10	2	1200
27657-104101	Acero inoxidable	B	19	4,25	10	10	4	3,4	5	2	4	1,5	180
27657-106101	Acero inoxidable	B	19	4,25	10	10	6	3,4	7	4	4	1,5	180
27657-106161	Acero inoxidable	B	40	10	16	20	6	4,3	7	4	10	2	500
27657-108161	Acero inoxidable	B	40	10	16	20	8	4,3	11	5	10	2	1200