

## Descripción del artículo/Imágenes del producto

19"



## Descripción


## Material:

Aluminio ovalado.

## Versión:

Superficie de acabado mate y colores naturales o negro anodizado.

## Planos

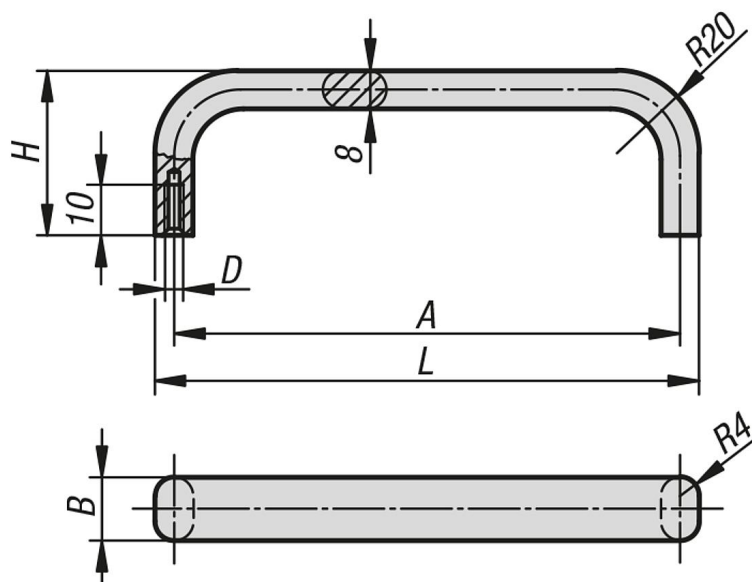

## Nuestros productos

Referencia	Color del cuerpo de base	A	B	D	H	L	Capacidad de carga N
06918-055051	negro	55	12	M5	40	63	500
06918-088051	negro	88	12	M5	40	96	500
06918-100051	negro	100	12	M5	40	108	500
06918-120051	negro	120	12	M5	40	128	500
06918-180051	negro	180	12	M5	40	188	500
06918-200051	negro	200	12	M5	40	208	500
06918-235051	negro	235	12	M5	40	243	500
06918-250051	negro	250	12	M5	40	258	500
06918-055053	natural	55	12	M5	40	63	500
06918-088053	natural	88	12	M5	40	96	500
06918-100053	natural	100	12	M5	40	108	500
06918-120053	natural	120	12	M5	40	128	500
06918-180053	natural	180	12	M5	40	188	500
06918-200053	natural	200	12	M5	40	208	500
06918-235053	natural	235	12	M5	40	243	500
06918-250053	natural	250	12	M5	40	258	500

Nuestros productos

---