

19"



**Descripción**


**Material:**

Puente de conexión de aluminio.  
Barra de soporte de plástico altamente resistente.

**Montaje:**

Desde la parte trasera.

Planos

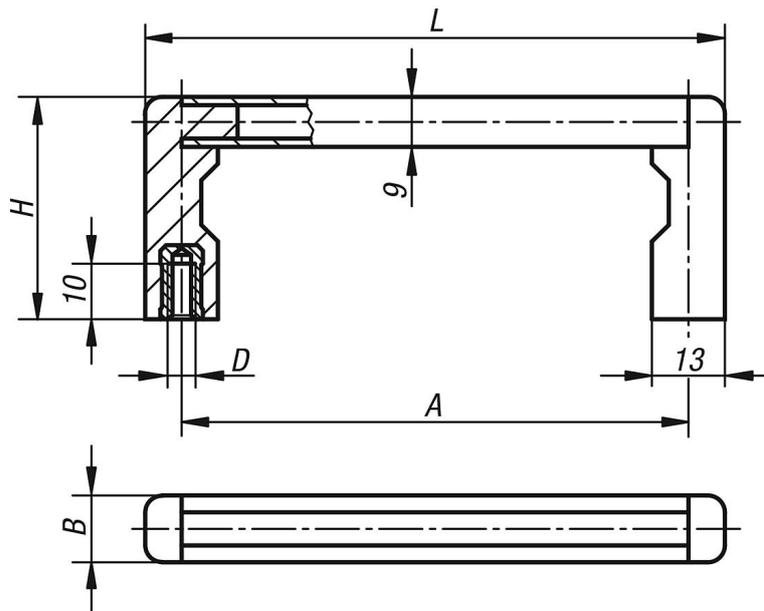

Nuestros productos

Referencia	Color del cuerpo de base	A	B	D	H	L	Capacidad de carga N
06933-05501	negro	55	12	M5	40	69	1000
06933-08801	negro	88	12	M5	40	102	1000
06933-10001	negro	100	12	M5	40	114	1000
06933-12001	negro	120	12	M5	40	134	1000
06933-18001	negro	180	12	M5	40	194	1000
06933-23501	negro	235	12	M5	40	249	1000
06933-05503	natural	55	12	M5	40	69	1000
06933-08803	natural	88	12	M5	40	102	1000
06933-10003	natural	100	12	M5	40	114	1000
06933-12003	natural	120	12	M5	40	134	1000
06933-18003	natural	180	12	M5	40	194	1000
06933-23503	natural	235	12	M5	40	249	1000

