

Descripción del artículo/Imágenes del producto



Descripción

Material:

Duroplast PF 31, negro.

Casquillo o perno roscado de acero inoxidable 1.4301.


Versión:

Con un brillo intenso.

A petición:

Otros colores.

Planos

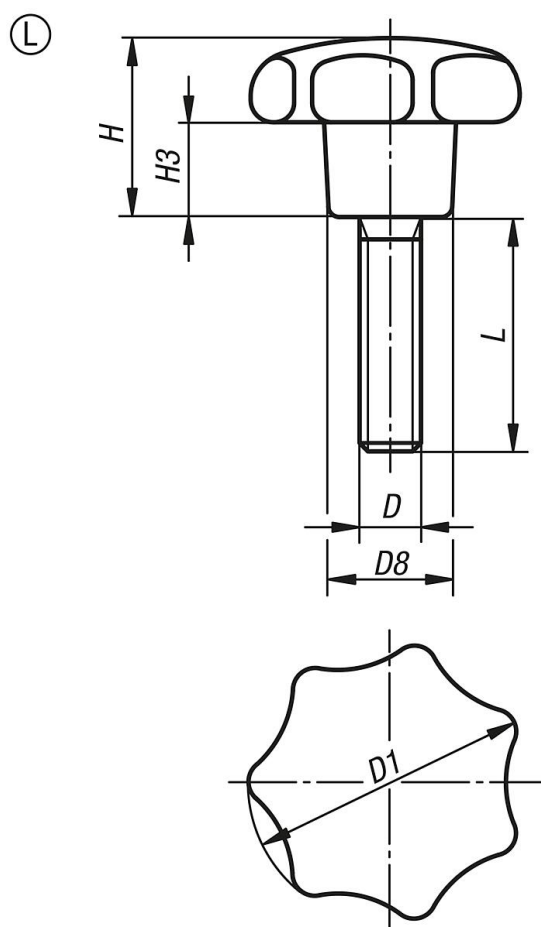

Nuestros productos

Referencia	Forma	D	D1	D8	H	H3	L
06209-42505X15	L	M5	25	12	16	8	15
06209-42505X20	L	M5	25	12	16	8	20
06209-42505X25	L	M5	25	12	16	8	25
06209-43206X15	L	M6	32	14	20	10	15
06209-43206X20	L	M6	32	14	20	10	20
06209-43206X25	L	M6	32	14	20	10	25
06209-43206X30	L	M6	32	14	20	10	30
06209-43206X40	L	M6	32	14	20	10	40
06209-44008X20	L	M8	40	18	25	13	20

06209_L Empuñaduras en estrella similares a DIN 6336, partes de acero inoxidable forma L con rosca exterior



Nuestros productos

Referencia	Forma	D	D1	D8	H	H3	L
06209-44008X25	L	M8	40	18	25	13	25
06209-44008X30	L	M8	40	18	25	13	30
06209-44008X40	L	M8	40	18	25	13	40
06209-44008X50	L	M8	40	18	25	13	50
06209-45010X25	L	M10	50	22	32	17	25
06209-45010X30	L	M10	50	22	32	17	30
06209-45010X40	L	M10	50	22	32	17	40
06209-45010X50	L	M10	50	22	32	17	50
06209-46312X30	L	M12	63	26	40	21	30
06209-46312X40	L	M12	63	26	40	21	40
06209-46312X50	L	M12	63	26	40	21	50
06209-46312X60	L	M12	63	26	40	21	60
06209-48016X30	L	M16	80	35	50	25	30
06209-48016X40	L	M16	80	35	50	25	40
06209-48016X50	L	M16	80	35	50	25	50
06209-48016X60	L	M16	80	35	50	25	60