


Descripción del artículo/Imágenes del producto



Descripción

Material:
GJL 250 recocido.

Planos

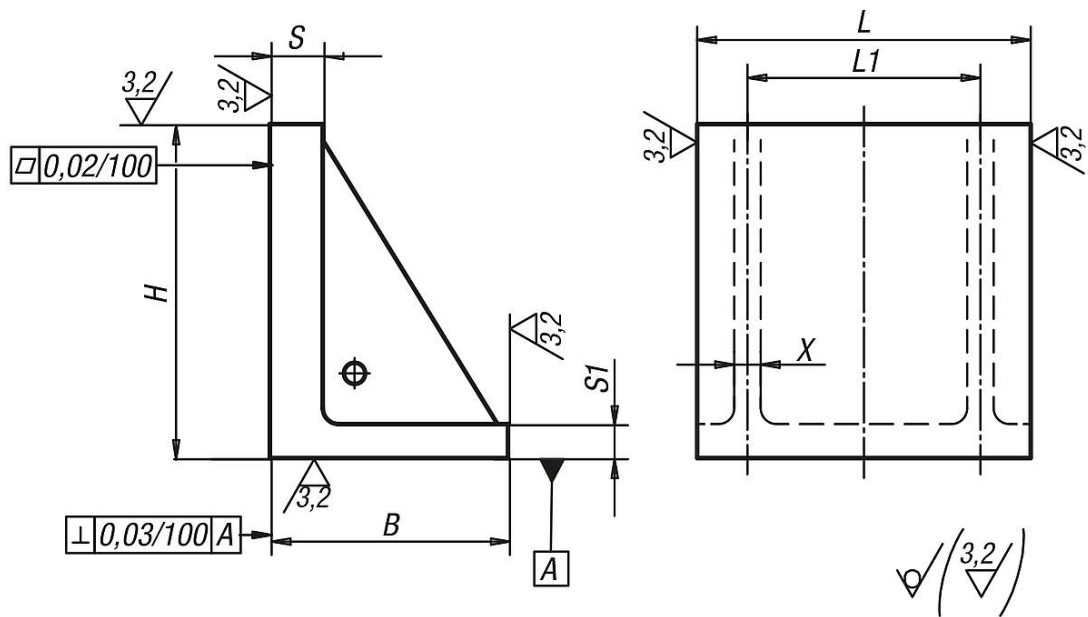

Nuestros productos

Referencia	Versión 1	L	L1	B	H	S	S1	X
01250-100125	sin ranura	100	40	100	125	20	10	10
01250-125160	sin ranura	125	100	100	160	20	10	10
01250-200250	sin ranura	200	120	125	250	30	15	15
01250-250300	sin ranura	250	200	150	300	40	20	20
01250-320370	sin ranura	320	280	200	370	50	25	25
01250-400450	sin ranura	400	280	265	450	60	30	30
01250-500550	sin ranura	500	360	315	550	70	35	35
01250-630640	sin ranura	630	520	350	640	80	40	35
01250-700750	sin ranura	700	600	400	750	80	40	40